


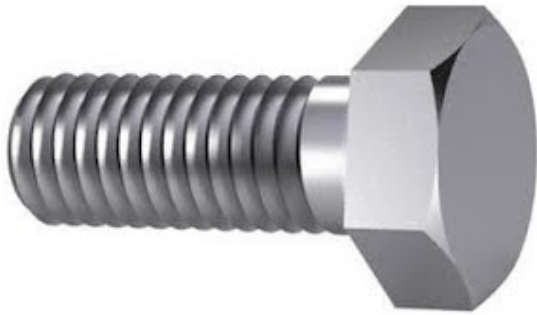

## Hexagon head screw ISO 4017/ DIN 933 Steel Zinc plated 8.8 M3X5

|                |               |
|----------------|---------------|
| Article number | 01210.030.005 |
| Brand          | -             |
| UBB            | 500645000646  |
| UNSPSC         | 31161620      |
| EAN            | 8717077049703 |
| PKG. of 500    | Full Box Only |

### Technical Parameters

|                   |               |
|-------------------|---------------|
| Diameter          | M3            |
| Length            | 5 mm          |
| Class             | 8.8           |
| Driving features  | Hexagon       |
| Head shape        | Hexagon head  |
| Material          | Steel         |
| Thread direction  | Right         |
| Surface treatment | Zinc plated   |
| Thread            | Metric thread |

### Standards

|      |            |
|------|------------|
| NF   | E25-114    |
| DIN  | 933        |
| ISO  | 4017       |
| ASME | B18.2.3.1M |
| NEN  | 1568       |

### Technical Specification

|        |     |
|--------|-----|
| d-D    | M3  |
| k      | 2   |
| L (mm) | 5   |
| P      | 0.5 |
| s      | 5.5 |

### Technical Drawing

