


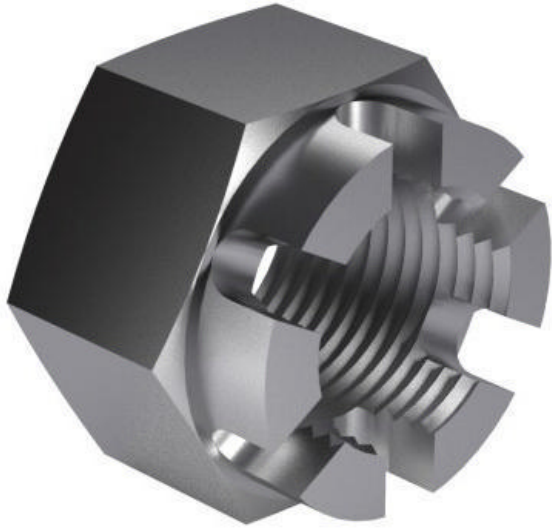

Hexagon slotted and castle nut DIN 935-1 Steel Plain 8 M36

Article number	12035.360.001
Brand	-
UBB	500648189040
UNSPSC	31161707
EAN	8717077216372
PKG. of 15	Full Box Only

Technical Parameters

Diameter	M36
Class	8
Driving features	Hexagon
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread

Info

* These dimensions are supplied with the 'old' widths across flats sizes according to DIN. Guide values for advised split pins (cotter pins) acc. to DIN 94 (ISO 1234). Depending on availability the dimensions may deviate.


Standards

DIN	935-1
NEN	729

Technical Specification

d-D	M36
m	38
n	7
Number of slots	6
P	4

Technical Drawing

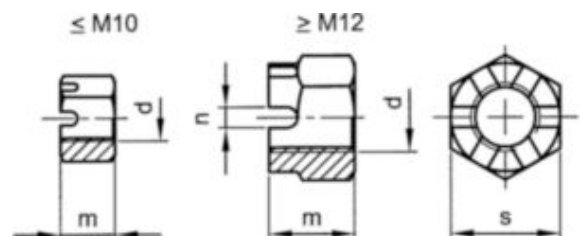

s

55

Split pin DIN 94

6.3