



Hexagon slotted and castle nut DIN 935-1 Steel Plain 10 M24

Article number	12040.240.001
Brand	-
UBB	500648190923
UNSPSC	31161707
EAN	8717077216563
PKG. of 25	Full Box Only

Technical Parameters

Diameter	M24
Class	10
Driving features	Hexagon
Material	Steel
Thread direction	Right
Surface treatment	Plain
Thread	Metric thread

Info * These dimensions are supplied with the 'old' widths across flats sizes according to DIN. Guide values for advised split pins (cotter pins) acc. to DIN 94 (ISO 1234). Depending on availability the dimensions may deviate.


Standards

NEN	729
DIN	935-1

Technical Specification

d-D	M24
m	27
n	5.5
Number of slots	6
P	3

Technical Drawing

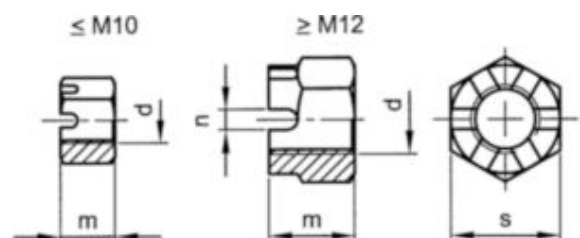

s

36

Split pin DIN 94

5