


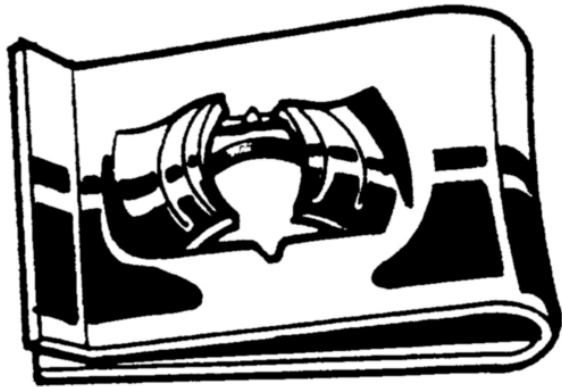

Speednut type SNU Spring steel Zinc plated ST2,9 (SNU 1812)

Article number	72294.029.001
Brand	-
UBB	500711720143
UNSPSC	31161725
EAN	8715494006262
PKG. of 100	Full Box Only

Technical Parameters

Diameter	2.9 mm
Material	Spring steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Self tapping thread

Standards

Technical Specification

a	11.1
b	7.9
c	4.8
D (mm)	2.9
For screw	ST2.9
m	4.8
s	0.7
t	0.7
Type	SNU

Technical Drawing

