


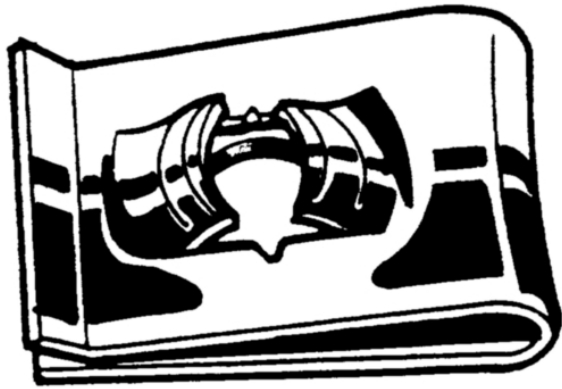

Speednut type SNU Spring steel Zinc plated ST4,8 (SNU 1747)

Article number	72294.048.002
Brand	-
UBB	500711720630
UNSPSC	31161725
EAN	8715494006316
PKG. of 50	Full Box Only

Technical Parameters

Diameter	4.8 mm
Material	Spring steel
Thread direction	Right
Surface treatment	Zinc plated
Thread	Self tapping thread

Standards

Technical Specification

a	12.2
b	16
c	5.5
D (mm)	4.8
For screw	ST4.8
m	7.9
s	0.7
t	0.9
Type	SNU

Technical Drawing

