


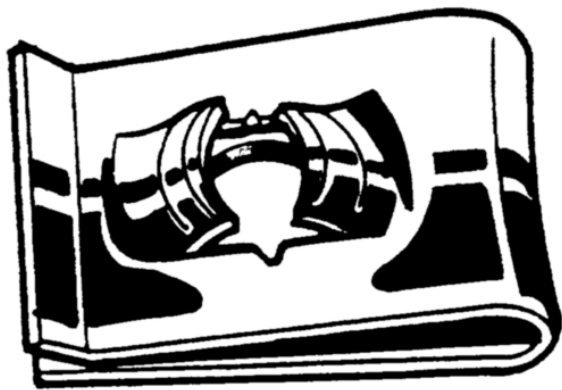

Speednut type SNU Spring steel Zinc plated 3,9MM= NR.05000050

|                |               |
|----------------|---------------|
| Article number | 72342.039.001 |
| Brand          | -             |
| UBB            | 500505278324  |
| UNSPSC         | 31161725      |
| EAN            | 8715494209762 |
| PKG. of 100    | Full Box Only |

Technical Parameters

|                   |                     |
|-------------------|---------------------|
| Diameter          | 3.9 mm              |
| Material          | Spring steel        |
| Thread direction  | Right               |
| Surface treatment | Zinc plated         |
| Thread            | Self tapping thread |

Standards

Technical Specification

|        |     |
|--------|-----|
| D (mm) | 3.9 |
|--------|-----|

Technical Drawing

