


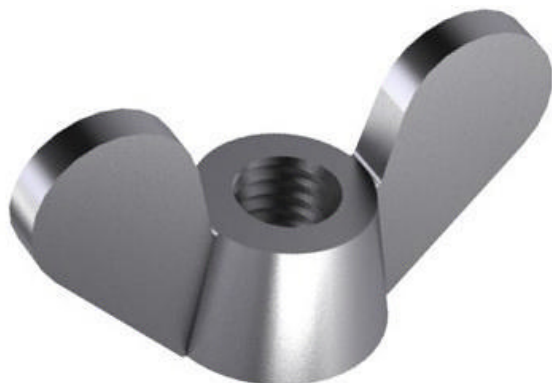

Szárnyas anya, kerek szárnyakkal DIN 315 Sárgaréz CU2/CU3 M3 (≠DIN)

Cikkszám	47550.030.001
Márka	-
UBB	950355292885
UNSPSC	31161717
EAN	8715492845757
csom. 250	Csak bontatlan csomagban

Műszaki adatok

Átmérő	M3
Behajtási tulajdonságok	Szárnyas
Anyag	Sárgaréz
Anyag, műszaki jellemzők	CU2/CU3
Menetirány	Jobb
Menetek	Metrikus menet

Info	do= Nominal diameter of drill bit.Min. td= Recommended drilling depth.hef= Effective anchorage depth.tfix= Grip range.s = Width across flats.kN = Load in kN.The allowable load is valid for one single anchor, at cracked concrete (tensile zone) with concrete class C20/25, incl. partial safety factor $\gamma_f = 1,4$ and if the Scr, N and Ccr, N are taken in to account.When
------	---

Szabványok

NEN	1625
BS	≈856
DIN	315

reduction on spacing and edge distance take place a re-calculation of forces should be carried out by making use of the technical guide or calculation software, they are available on request. Final calculations should comply with the complete European Technical Approval (ETA), this approval is also available on request.

Műszaki **specifikációk**

d-D	M3
e (max.)	17.6
h (max.)	8.6
m (min.)	2.9
P	0.5

Műszaki **rajz**

